


Double nipple NPFC-D-2G18-M-F1A

Part number: 8133311

FESTO

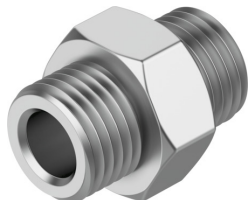

Data sheet

Feature	Value
Material threaded fitting	High-alloy stainless steel
Operating medium	Compressed air to ISO 8573-1:2010 [-::-]
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Suitability for the production of Li-ion batteries	Product corresponds to the internal product definition from Festo for use in battery production:Metals with more than 1% by mass of copper, zinc or nickel are excluded from use.The exceptions are nickel in steel, chemically nickel-plated surfaces, printed circuit boards, cables, electrical plug connectors and coils
Product weight	10 g
Pneumatic connection, port 1	G1/8
Pneumatic connection, port 2	G1/8
Note on materials	RoHS-compliant