


**Sub-base**  
**VMPA1-AP-4-EMM-8-SK**  
Part number: 8157743

**FESTO**

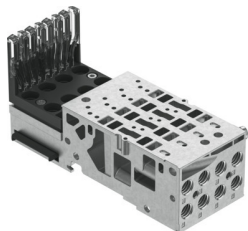

**Data sheet**

| Feature                        | Value                                  |
|--------------------------------|----------------------------------------|
| Width                          | 42 mm                                  |
| Length                         | 107.3 mm                               |
| Grid dimension                 | 10.5 mm                                |
| Max. number of valve positions | 4                                      |
| Operating pressure             | -0.09 MPa...1 MPa<br>-0.9 bar...10 bar |
| Pilot pressure                 | 0.3 MPa...0.8 MPa<br>3 bar...8 bar     |
| Corrosion resistance class CRC | 0 - No corrosion stress                |
| LABS (PWIS) conformity         | VDMA24364 zone III                     |
| Storage temperature            | -20 °C...60 °C                         |
| Ambient temperature            | -5 °C...50 °C                          |
| Product weight                 | 180 g                                  |
| Pneumatic connection, port 2   | M7                                     |
| Pneumatic connection, port 4   | M7                                     |
| Note on materials              | RoHS-compliant                         |
| Material sub-base              | Die-cast aluminium                     |