


Sub-base VABS-K2-12S-20-N18-P

Part number: 8186870

FESTO

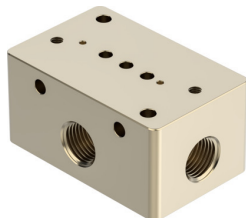

Data sheet

| Feature | Value |
|---|---|
| Size | 12 |
| Nominal size | 2 mm |
| Valve size | 12 mm |
| Fluid connection | Female thread 1/8 NPT |
| Mounting position | optional |
| Design | Connection direction at side |
| Max. number of valve positions | 1 |
| Flow direction | Non-reversible |
| Operating medium | Liquid media Gaseous media |
| Note on operating and pilot medium | Observe resistance of materials that come into contact with the media |
| Corrosion resistance class CRC | 0 - No corrosion stress |
| LABS (PWIS) conformity | VDMA24364 zone III |
| Storage temperature | -20 °C...70 °C |
| Suitable for use with food | See supplementary material information |
| Media temperature | 0 °C...50 °C |
| Ambient temperature | 0 °C...50 °C |
| Max. tightening torque for valve mounting | 0.33 Nm |
| Max. tightening torque for fitting | 7 Nm |
| Max. tightening torque | 0.6 Nm |
| Product weight | 31 g |
| Mounting method for sub-base | With through-hole |
| Mounting method for valve | Via female thread |
| Note on materials | RoHS-compliant |
| Material sub-base | PEEK |