


**Sub-base**  
**VABS-K3-16S-20-U14-P**  
Part number: 8187600

**FESTO**

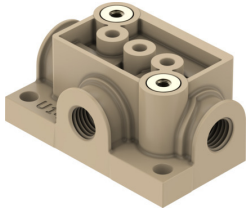

**Data sheet**

Feature	Value
Size	16
Nominal size	2 mm
Valve size	16 mm
Fluid connection	Female thread 1/4-28 UNF-2B
Mounting position	optional
Design	Connection direction at side
Max. number of valve positions	1
Flow direction	Reversible
Operating medium	Liquid media Gaseous media
Note on operating and pilot medium	Observe resistance of materials that come into contact with the media
Corrosion resistance class CRC	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-20 °C...70 °C
Suitable for use with food	See supplementary material information
Media temperature	0 °C...50 °C
Ambient temperature	0 °C...50 °C
Max. tightening torque for valve mounting	0.3 Nm
Max. tightening torque for fitting	0.5 Nm
Max. tightening torque	0.6 Nm
Product weight	9 g
Mounting method for sub-base	With through-hole
Mounting method for valve	Via female thread
Note on materials	RoHS-compliant
Material sub-base	PEEK