


# Blanking plug NPQX-P-PC15

Part number: 8191751

FESTO

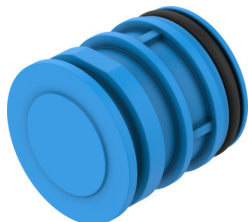

## Data sheet

Feature	Value
Size	Standard
Mounting position	optional
Size of pack	10
Operating pressure	-0.1 MPa...1 MPa -1 bar...10 bar -14.5 psi...145 psi
Operating medium	Compressed air to ISO 8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (in which case lubricated operation will always be required)
Corrosion resistance class CRC	3 - high corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C...60 °C
Product weight	1.6 g
Type of mounting	Via retaining clamp
Note on materials	RoHS-compliant
Material blanding plug	PA-reinforced
Material o-ring	HNBR