


Suction cup with connector OGVM-30X65-AV-N-RA

Part number: 8213253

FESTO

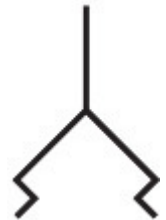

Data sheet

Feature	Value
Height compensator for suction cup	7 mm
Min. workpiece radius	15 mm
Nominal size	6 mm
Suction cup size	30x65 mm
Suction cup volume	11.5 cm ³
Position of connection	Top
Mounting position	optional
Suction cup shape	Oval, bellows, 1.5 convolutions
Operating pressure	-95 kPa...0 kPa -0.95 bar...0 bar -13.775 psi...0 psi
Nominal operating pressure	-60 kPa -0.6 bar -8.7 psi
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:::-]
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-A1/A2-L
Ambient temperature	-20 °C...80 °C
Holding force at nominal operating pressure	66 N
Vertical lateral force at nominal operatin pressure	104 N
Product weight	56 g
Type of mounting	Via vacuum port
Vacuum connection	Rectangular adapter RA
Colour	Black
Shore hardness	60 +/- 5
Material screwed plug	Wrought aluminium alloy
Note on materials	RoHS-compliant
Material suction cup	NBR