


Bulkhead quick connector QCK-3/8-PK-9-B

Part number: 9427

FESTO

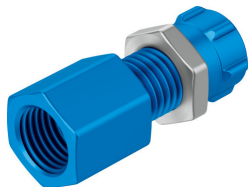

Data sheet

| Feature | Value |
|---|---|
| Nominal size | 8 mm |
| Type of seal on screwed plug | Sealing ring |
| Mounting position | optional |
| Design | Bulkhead |
| Operating pressure complete temperature range | -0.095 MPa...1 MPa -0.95 bar...10 bar -13.775 psi...145 psi |
| Operating medium | Compressed air to ISO 8573-1:2010 [7:-:-] |
| Note on operating and pilot medium | Lubricated operation possible |
| Corrosion resistance class CRC | 1 - Low corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Ambient temperature | -10 °C...60 °C |
| Nominal torque | 12.5 Nm |
| Tolerance for nominal tightening torque | ± 20% |
| Pneumatic connection, port 1 | Female thread G3/8 |
| Pneumatic connection, port 2 | For barbed fitting inside diameter of 9 mm with nut |
| Material union nut | Wrought aluminium alloy, anodised |
| Note on materials | RoHS-compliant |
| Material nut | Galvanised steel |
| Material connector | Wrought aluminium alloy, anodised |