


Indicating plug MCL-230AC

Part number: 10001

FESTO

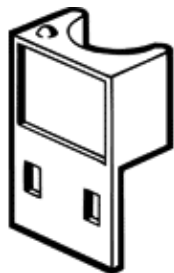

Data sheet

| Feature | Value |
|--|---|
| Product weight | 12 g |
| Electrical connection | Plug pattern type A to EN 175301-803 Plug Per DIN EN 175301-803 |
| Nominal operating voltage, AC | 230 V |
| Line frequency | 50 ... 60 Hz |
| Permissible voltage fluctuation | -20 % / +15 % |
| Protection class | IP65 to IEC 60529 |
| Ambient temperature | -20 ... 60 °C |
| CE symbol (see declaration of conformity) | according to EU low voltage guideline |
| UKCA marking (see declaration of conformity) | To UK instructions for electrical equipment |
| PWIS conformity | VDMA24364-B2-L |
| Material housing | PA6 reinforced |