 



# OR gate OS-1/4-NPT

Part number: 10413

FESTO

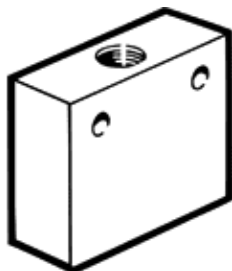

## Data sheet

Feature	Value
Valve function	OR function
Pneumatic connection, port 1	1/8 NPT
Pneumatic connection, port 2	1/8 NPT
Mounting type	with through hole
Standard nominal flow rate	1,170 l/min
Working pressure	1 ... 10 bar
Ambient temperature	-10 ... 60 °C
Material housing	Wrought Aluminum alloy
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Nominal size	6.5 mm
Assembly position	Any
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B1/B2-L
Medium temperature	-10 ... 60 °C
Product weight	110 g
Pneumatic connection, port 3	NPT1/8-27
Materials note	Conforms to RoHS
Material seals	NBR