

 

# Stem actuated valve

## V/O-3-PK-3

Part number: 10747

FESTO

With barbed fitting connection for 3mm ID tubing.

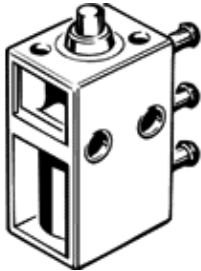

### Data sheet

| Feature                             | Value   |
|-------------------------------------|---|
| Valve function                      | 3/2 open/closed, monostable                             |
| Type of actuation                   | mechanical  |
| Standard nominal flow rate          | 80 l/min  |
| Working pressure                    | 0 ... 8 bar   |
| Design structure                    | Piston seat   |
| Nominal size                        | 2.5 mm  |
| Type of piloting                    | direct  |
| Operating medium                    | Compressed air in accordance with ISO8573-1:2010 [-:~:] |
| PWIS conformity                     | VDMA24364-B1/B2-L                                       |
| Ambient temperature                 | -10 ... 60 °C   |
| Actuating force                     | 17 N  |
| Actuating force for normally closed | 17 N  |
| Actuating force for normally open   | 24 N  |
| Product weight                      | 20 g  |
| Mounting type                       | with through hole                                       |
| Pneumatic connection, port 1        | PK-3  |
| Pneumatic connection, port 2        | PK-3  |
| Pneumatic connection, port 3        | PK-3  |
| Material seals                      | NBR   |
| Material housing                    | POM   |