


# Shock absorber DYEF-S-M12-Y1

Part number: 1153004

FESTO

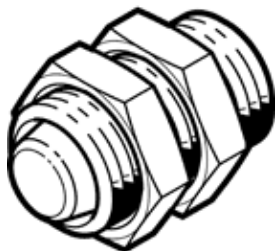

## Data sheet

Feature	Value
Size	M12
Stroke	1.2 mm
Cushioning	P cushioning without metal fixed stop
Assembly position	Any
Position detection	No
Max. impact speed	0.8 m/s
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	0 ... 60 °C
Cushioning length	1.2 mm
Max. energy consumption per stroke	0.35 J
Product weight	15 g
Mounting type	with lock nut
Materials note	Conforms to RoHS
Material seals	NBR
Material housing	High alloy steel