

 

Silencer

AMTE-M-LH-N12

Part number: 1206992

FESTO

Suitable for reducing noise at the exhaust ports of pneumatic systems.

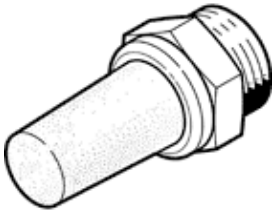

Data sheet

Feature	Value
Assembly position	Any
Container size	10
Operating pressure MPa	0 ... 1 MPa
Working pressure	0 ... 10 bar
Flow rate to atmosphere	9,240 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B2-L
Sound pressure level	85 dB(A)
Ambient temperature	-40 ... 80 °C
Product weight	46 g
Pneumatic connection	1/2 NPT
Material of silencer insert	Bronze
Material of threaded plug	Brass
Materials note	Conforms to RoHS