


Adapter plate

VABA-S6-7-S2-3-P-N1

Part number: 1302085
Product to be discontinued

FESTO

Type to be discontinued. Available until 2026. See Support Portal for alternative products.

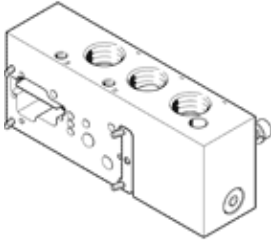

Data sheet

Feature	Value
Width	60 mm
Assembly position	Any
Max. number of solenoid coils	26
Working pressure	-0.9 ... 10 bar
Nominal operating voltage DC	24 V
Permissible voltage fluctuation	+/- 10 %
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Protection class	IP65 NEMA 4
Ambient temperature	-5 ... 50 °C
Product weight	2,600 g
Auxiliary pilot air port 12	1/8 NPT
Auxiliary pilot air port 14	1/8 NPT
Pneumatic connection, port 1	1 1/2 NPT
Pneumatic connection, port 3	1 1/2 NPT
Pneumatic connection, port 5	1 1/2 NPT
Materials note	Conforms to RoHS
Material seals	NBR
Material plate	Wrought Aluminum alloy
Material screws	Steel Galvanized