


# Push-in T-fitting QSMT-B-M5-4-20

Part number: 130905  
Product to be discontinued

FESTO

360° orientable, male thread with external hexagon.  
Type to be discontinued. Available until 2018. See Support Portal for alternative products.

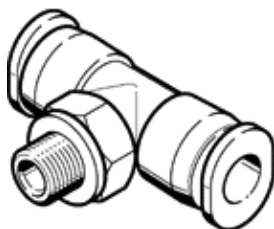

## Data sheet

| Feature                                       | Value   |
|---|---|
| Size  | Mini  |
| Nominal size                                  | 2.2 mm  |
| Type of seal on screw-in stud                 | Sealing ring  |
| Assembly position                             | Any   |
| Container size                                | 20  |
| Design structure                              | Push/pull principle                                     |
| Operating pressure complete temperature range | -0.95 ... 10 bar  |
| Operating medium                              | Compressed air in accordance with ISO8573-1:2010 [7:::] |
| Note on operating and pilot medium            | Lubricated operation possible                           |
| Corrosion resistance classification CRC       | 1   |
| Ambient temperature                           | -10 ... 60 °C   |
| Authorization                                 | Germanischer Lloyd                                      |
| Max. tightening torque                        | 1.5 Nm  |
| Product weight                                | 4.3 g   |
| Number of outputs                             | 2   |
| Number of supply lines                        | 1   |
| Pneumatic connection, port 1                  | Male thread M5  |
| Pneumatic connection, port 2                  | for tubing, 4mm outside diameter                        |
| color of release ring                         | blue  |
| Materials note                                | Conforms to RoHS  |
| Materials information, housing                | PBT   |
| Release ring material data                    | POM   |
| Materials information for tubing seal         | NBR   |
| Hose clamping segment material data           | High alloy steel, non-corrosive                         |