


# Push-in T connector

## QST-B-6-20

Part number: 130974  
Product to be discontinued

FESTO

Type to be discontinued. Available until 2018. See Support Portal for alternative products.

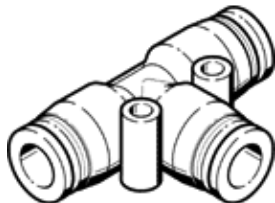

### Data sheet

| Feature                                       | Value  |
|---|--|
| Size  | Standard   |
| Nominal size                                  | 3.3 mm   |
| Assembly position                             | Any  |
| Container size                                | 20   |
| Design structure                              | Push/pull principle                                      |
| Operating pressure complete temperature range | -0.95 ... 10 bar   |
| Operating medium                              | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| Note on operating and pilot medium            | Lubricated operation possible                            |
| Corrosion resistance classification CRC       | 1  |
| Ambient temperature                           | -10 ... 60 °C  |
| Authorization                                 | Germanischer Lloyd                                       |
| Product weight                                | 11 g   |
| Number of outputs                             | 2  |
| Number of supply lines                        | 1  |
| Pneumatic connection, port 1                  | For tubing outside diameter 6 mm                         |
| Pneumatic connection, port 2                  | for tubing, 6mm outside diameter                         |
| color of release ring                         | blue   |
| Materials note                                | Conforms to RoHS   |
| Materials information, housing                | PBT  |
| Release ring material data                    | POM  |
| Materials information for tubing seal         | NBR  |
| Hose clamping segment material data           | High alloy steel, non-corrosive                          |