


Push-in fitting QS-B-1/2-12-I-10

Part number: 132001
Product to be discontinued

FESTO

male thread with internal hexagon socket.

Type to be discontinued. Available until 2018. See Support Portal for alternative products.

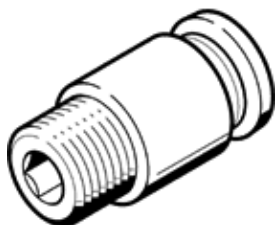

Data sheet

Feature	Value
Size	Standard
Nominal size	7.1 mm
Type of seal on screw-in stud	coating
Assembly position	Any
Container size	10
Design structure	Push/pull principle
Operating pressure complete temperature range	-0.95 ... 10 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:::]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1
Ambient temperature	-10 ... 60 °C
Authorization	Germanischer Lloyd
Max. tightening torque	28 Nm
Product weight	49 g
Pneumatic connection, port 1	Male thread R1/2
Pneumatic connection, port 2	for tubing, 12mm outside diameter
color of release ring	blue
Materials note	Conforms to RoHS
Materials information, housing	Brass Nickel plated
Release ring material data	POM
Materials information for tubing seal	NBR
Hose clamping segment material data	High alloy steel, non-corrosive