


# Push-in/threaded L-fitting NPQP-LQ-R18-Q8-FD-P10

Part number: 133065

FESTO

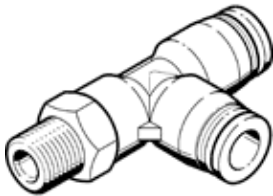

## Data sheet

Feature	Value
Size	Standard
Nominal size	4.8 mm
Design	L-shape, additional push-in connector, lengthwise
Container size	10
Design structure	Push/pull principle
Temperature dependent working pressure	-0.95 ... 10 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	4 - Very high corrosion stress
PWIS conformity	VDMA24364 zone III
Food-safe	See Supplementary material information
Ambient temperature	-20 ... 60 °C
Product weight	11 g
Mounting type	External hex A/F 14
Pneumatic connection, port 1	Male thread R1/8
Pneumatic connection, port 2	For tubing outside diameter 8 mm
Materials note	Conforms to RoHS
Material housing	PP
Material of tube retaining claw	High alloy steel, non-corrosive