


Clamping sleeve EAMH-60-6.35-C18.1-P

Part number: 1354096

FESTO

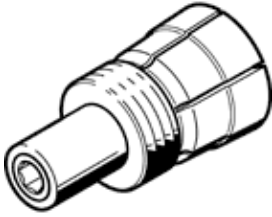

Data sheet

| Feature | Value |
|------------------------|------------------------|
| Size | 60 |
| Assembly position | Any |
| Max. speed | 6,000 1/min |
| PWIS conformity | VDMA24364-B2-L |
| Storage temperature | -25 ... 60 °C |
| Relative air humidity | 0 - 95 % |
| Ambient temperature | -10 ... 60 °C |
| Mass moment of inertia | 1.56 kgmm ² |
| Product weight | 43 g |
| Materials note | Conforms to RoHS |