

Manifold strip


VABM-C8-12E-G14-28-M1-L

Part number: 1361877

Classic - do not use for new projects

FESTO

Modern alternatives can be found by entering the first four characters of the type code in the search field.

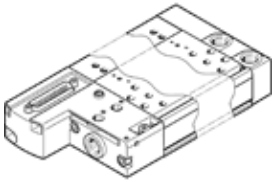

Data sheet

Feature	Value
Grid dimension	12 mm
Max. number of valve positions	28
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Max. tightening torque, valve mounting	0.6 Nm
Max. tightening torque, wall mounting	5 Nm
Product weight	1,704 g
Pneumatic connection, port 1	G1/4
Pneumatic connection, port 3	G1/4
Pneumatic connection, port 5	G1/4
Materials note	Conforms to RoHS
Material manifold	Wrought Aluminum alloy