


Parallel kit EAMM-U-110-D80-100A-120-S1

Part number: 1433650

FESTO

Suitable for electric drives.

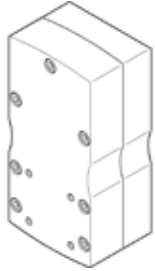

Data sheet

| Feature | Value |
|--------------------------|-----------------------|
| Size | 110 |
| Assembly position | Any |
| Gear unit ratio | 1:1 |
| Max. speed | 5,000 1/min |
| PWIS conformity | VDMA24364 zone III |
| Storage temperature | -25 ... 60 °C |
| Relative air humidity | 0 - 95 % |
| Protection class | IP65 |
| Ambient temperature | -10 ... 60 °C |
| Mass moment of inertia | 799 kgmm ² |
| No-load driving torque | 0.3 Nm |
| Transferable torque | 25 Nm |
| Product weight | 5,140 g |
| Interface code, actuator | D80B |
| Interface code, motor in | 100A |
| Materials note | Conforms to RoHS |