


Subbase PAML-CP-90-HP3-G114

Part number: 1448978

FESTO

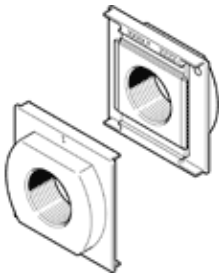

Data sheet

Feature	Value
Size	90
Nominal diameter DN	36
Series	L
Operating pressure MPa	0 ... 5 MPa
Working pressure	0 ... 50 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [-:-:-]
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B2-L
Storage temperature	-10 ... 60 °C
Food-safe	See Supplementary material information
Medium temperature	5 ... 60 °C
Ambient temperature	5 ... 60 °C
Product weight	500 g
Pneumatic connection, port 1	G1 1/4
Pneumatic connection, port 2	G1 1/4
Materials note	Conforms to RoHS
Material of connecting plate	Wrought Aluminum alloy
Material seals	NBR
Material screws	Stainless steel