


Coupling EAMC-42-50-10-12

Part number: 1455666

FESTO

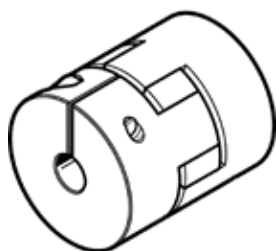

Data sheet

Feature	Value
Holder diameter 1	10 mm
Holder diameter 2	12 mm
Size	42
Nominal length	50 mm
Assembly position	Any
Max. speed	6,000 1/min
PWIS conformity	VDMA24364-B2-L
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Ambient temperature	-25 ... 60 °C
Mass moment of inertia	34.8 kgmm ²
Transferable torque	17 Nm
Product weight	145 g
Materials note	Conforms to RoHS