


Programming cable KDI-SB202-BU9

Part number: 150268

FESTO

Festo standard, serial diagnosis cable, from one valve manifold to the Checkbox.

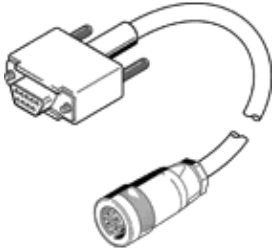

Data sheet

Feature	Value
Permissible cable diameter	4.5 ... 6.5 mm
Assembly position	Any
Operating voltage range AC	≤ 300 V
Ambient temperature with flexible cable installation	-10 ... 80 °C
Ambient temperature	-30 ... 80 °C
Product weight	181 g
Electrical connection 1	Straight socket, M12, 4-pin
Electrical connection 2	Straight socket, Sub-D, 9-pin
Cable structure	4x0,14
Cable length	5 m
Mounting type	Clip With sleeve nut
Materials information for locknut	Brass Nickel plated
Materials information, housing	PBT
Materials information, cable sheaths	PUR
Material information for crimp connectors	Copper alloy Gold plated