


# Guide unit FENG-1 1/4"- -KF

Part number: 151746

FESTO

with recirculating ball bearing guide, serves for protection against rotation, provides a high accuracy of guidance.

Type to be discontinued. Available until 2021. See Support Portal for alternative products.

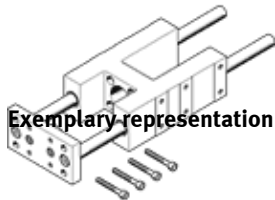

## Data sheet

| Feature                            | Value                            |
|------------------------------------|----------------------------------|
| Size                               | 1 1/4"                           |
| Stroke                             | 0.4 ... 20 "                     |
| Assembly position                  | Any                              |
| Guide                              | Recirculating ball bearing guide |
| Design structure                   | Guide                            |
| Ambient temperature                | -4 ... 176 °F                    |
| Displacement force                 | 15 N                             |
| Additional weight per 10 mm stroke | 18 g                             |
| Basic weight for 0 mm stroke       | 1,530 g                          |
| Mounting type                      | with internal (female) thread    |
| Material of guide component        | Heat-treatment steel             |
| Material housing                   | Wrought Aluminum alloy           |