


Guide unit FENG-2 1/2"- -KF

Part number: 151749

FESTO

with recirculating ball bearing guide, serves for protection against rotation, provides a high accuracy of guidance.

Type to be discontinued. Available until 2021. See Support Portal for alternative products.

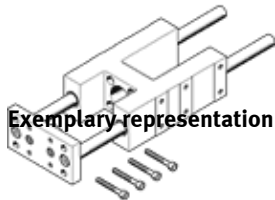

Data sheet

| Feature | Value |
|------------------------------------|----------------------------------|
| Size | 2 1/2" |
| Stroke | 0.4 ... 20 " |
| Assembly position | Any |
| Guide | Recirculating ball bearing guide |
| Design structure | Guide |
| Ambient temperature | -4 ... 176 °F |
| Displacement force | 15 N |
| Additional weight per 10 mm stroke | 50 g |
| Basic weight for 0 mm stroke | 5,410 g |
| Mounting type | with internal (female) thread |
| Material of guide component | Heat-treatment steel |
| Material housing | Wrought Aluminum alloy |