


Linear actuator DGO-1/2"- -P-A-B

Part number: 15227

FESTO

For proximity sensing, rodless, with magnetic coupling.
Old part no. 13003431

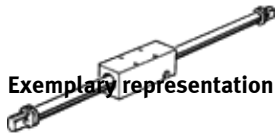

Data sheet

Feature	Value
Stroke	0.04 ... 157 "
Piston diameter	1/2"
Cushioning	P: Flexible cushioning rings/plates at both ends
Guide	Plain-bearing guide
Working pressure	2 ... 7 bar
Mode of operation	double-acting
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B2-L
Ambient temperature	-20 ... 60 °C
Theoretical force at 0.6 MPa (6 bar, 87 psi), retracting	68 N
Theoretical force at 0.6 MPa (6 bar, 87 psi), advance	68 N
Pneumatic connection	10-32 UNF-2B