
 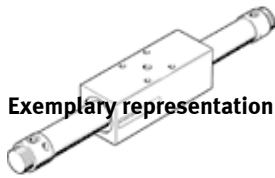


# Linear actuator DGO-3/4"- -PPV-A-B

Part number: 15229

FESTO

For proximity sensing, rodless, with magnetic coupling.



## Data sheet

Feature	Value
Stroke	0.04 ... 157 "
Piston diameter	3/4"
Cushioning	PPV: Pneumatic cushioning adjustable at both ends
Guide	Plain-bearing guide
Driver principle	force-locking (magnet)
Working pressure	1.6 ... 7 bar
Mode of operation	double-acting
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
PWIS conformity	VDMA24364-B2-L
Ambient temperature	-20 ... 60 °C
Cushioning length	17 mm
Pneumatic connection	1/8 NPT