


# Multi-socket KDVF6-12

Part number: 152510

FESTO

For multi-tube connection of plastic 6mm ID tubing.

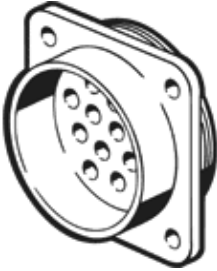

## Data sheet

Feature	Value
Nominal size	6 mm
Working pressure	-0.95 ... 10 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Max. number of connections	12
Pneumatic connection	PK-6
Color	Grey
Materials note	Conforms to RoHS