

Push-in T-fitting QSTL-3/8-5/16-U


Part number: 153718

FESTO

rotatable by 360°, male thread with external hexagon.

This product is only available if ordered from the Festo Corporation, USA.

Type to be discontinued. Available until 2011.

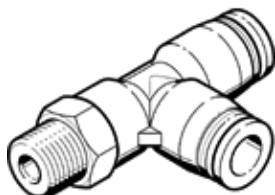

Data sheet

| Feature | Value |
|---|------------------------------------|
| Size | Standard |
| Nominal size | 5 mm |
| Type of seal on screw-in stud | coating |
| Assembly position | Any |
| Container size | 1 |
| Design structure | Push/pull principle |
| Working pressure | -0.95 ... 10 bar |
| Temperature dependent working pressure | -0.95 ... 10 bar |
| Operating medium | Filtered compressed air Vacuum |
| Corrosion resistance classification CRC | 1 |
| Ambient temperature | -10 ... 60 °C |
| Authorization | Germanischer Lloyd |
| Max. tightening torque | 24 Nm |
| Number of outputs | 2 |
| Number of supply lines | 1 |
| Pneumatic connection, supply line | Male thread NPT3/8-18 |
| Pneumatic connection, output | for tubing, 5/16" outside diameter |
| color of release ring | Grey |
| Materials note | Conforms to RoHS |
| Materials information, housing | PBT |
| Release ring material data | POM |
| Materials information for tubing seal | NBR |
| Hose clamping segment material data | High alloy steel, non-corrosive |