


Swivel flange SUA-12/16

Part number: 157319

FESTO

For cylinders ADVU, AEVU. Matching clevis foot mounts LBN, LN, or LSN.

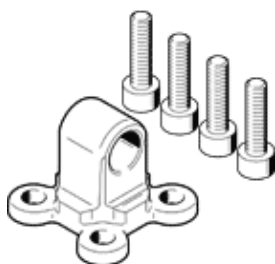

Data sheet

Feature	Value
Size	12/16
Assembly position	Any
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-40 ... 90 °C
Product weight	22 g
Materials note	Conforms to RoHS
Material mounting	Wrought Aluminum alloy
Material mounting pin	steel, galvanized
Material sleeve	Spring steel
Material bearing	Plastic
Material screws	Galvanized steel
Material lock	Spring steel
Material shaft	Steel With protective coating