


Swivel flange SUA-100

Part number: 157327

FESTO

For cylinders ADVU, AEVU. Matching clevis foot mounts LBN, LN, or LSN.

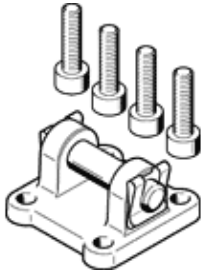

Data sheet

Feature	Value
Size	100
Assembly position	Any
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-40 ... 90 °C
Product weight	1,285 g
Materials note	Conforms to RoHS
Material mounting	Wrought Aluminum alloy
Material mounting pin	steel, galvanized
Material sleeve	Spring steel
Material bearing	Plastic
Material disc	steel, galvanized
Material screws	Galvanized steel
Material lock	steel, galvanized
Material shaft	Steel With protective coating