


# Connecting cable

## NHSB-A1-25-BLG5-LE5-PU8-2XBB

Part number: 1585797

FESTO

Suitable for use with linear actuator DFPI.

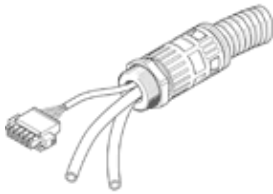

## Data sheet

Feature	Value
Protective tube length	25 m
Assembly position	Any
Outdoor use	C1 - weather protected locations of use
Operating voltage range DC	0 ... 30 V
Relative air humidity	5 - 100 % Condensing
Protection class	IP65 IP67 IP68 IP69K NEMA 4
Ambient temperature	-20 ... 60 °C
Ambient temperature with flexible cable installation	-5 ... 60 °C
Electrical connection 1	Straight plug, 5-pin
Electrical connection 2	Open end, 5-wire
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible
Pneumatic connection	For tubing outside diameter 10 mm For tubing outside diameter 8 mm
Min. cable bending radius	100 mm
Cable structure	5 x 0,75 mm <sup>2</sup>
Product weight	6,250 g
Materials note	Contains PWIS substances Conforms to RoHS
Materials information for conduit	PA
Information on materials, protective conduit fitting	PA
Materials information, cable sheaths	PVC
Materials information for seals	TPE