


Compressed air reservoir CRVZS-0.4

Part number: 160234

FESTO

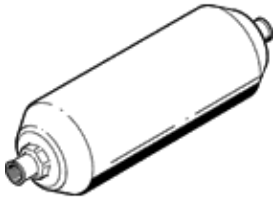

Data sheet

Feature	Value
Volume	0,4 l
Assembly position	Any
Conforms to standard	AD 2000 reference sheet
Operating pressure MPa	-0.095 ... 1.6 MPa
Working pressure	-0.95 ... 16 bar
Operating pressure	-13.78 ... 232 psi
Authorization	CRN TÜV
Certificate issuing department	TSSACRN0H17477.5C
Operating medium	Compressed air in accordance with ISO8573-1:2010 [-:~:] Nitrogen
Corrosion resistance classification CRC	3 - High corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Food-safe	See Supplementary material information
Medium temperature	-10 ... 100 °C
Ambient temperature	-10 ... 100 °C
Max. tightening torque, connecting thread	23 Nm
Product weight	543 g
Mounting type	Fixing clips
Pneumatic connection	G1/4
Materials note	Conforms to RoHS
Material of air reservoir	High alloy steel, non-corrosive
Material fixing clips	High alloy steel, non-corrosive