


# Vacuum filter VAF-PK-6

Part number: 160239

FESTO

In-line design.

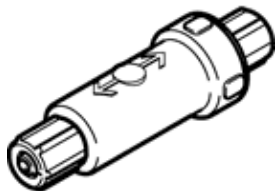

## Data sheet

Feature	Value
Nominal size	4.6 mm
Assembly position	Any
Grade of filtration	50 µm
Working pressure	-0.95 ... 0 bar
Note on working pressure	Only for application in open vacuum systems
Flow rate at negative pressure of -0.075 MPa (-0.75 bar, -10.875 psi)	210 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	0 ... 40 °C
Product weight	10 g
Mounting type	Line installation
Pneumatic connection	PK-6 with union nut
Material of union nut	POM
Materials note	Conforms to RoHS
Material filter	Mesh PA
Material housing	PA
Ejector pulse suitability	≤ 8 bar