 



# Hand slide valve VBOH-32-M5

Part number: 1609969

FESTO

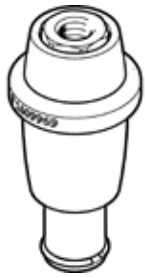

## Data sheet

Feature	Value
Valve function	3/2 bistable
Pneumatic connection, port 1	M5
Pneumatic connection, port 2	M5
Type of actuation	manual
Mounting type	Line installation Threaded
Standard nominal flow rate	236 l/min
Nominal size	3.6 mm
Operating pressure MPa	-0.095 ... 1.2 MPa
Working pressure	-0.95 ... 12 bar
Ambient temperature	-10 ... 80 °C
Material housing	Anodised wrought aluminium alloy
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Grid dimension	17 mm
Sealing principle	soft
Assembly position	Any
Design structure	Sleeve slide
Type of piloting	direct
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B2-L
Medium temperature	-10 ... 80 °C
Actuating force	14 N
Product weight	8 g
Material of threaded plug	Anodised wrought aluminium alloy
Materials note	Conforms to RoHS
Material seals	NBR