


# Encoder cable NEBM-M12G8-E-15-S1G9-V4

Part number: 1617287

FESTO

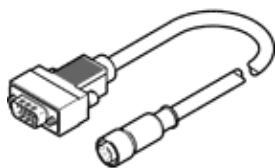

## Data sheet

Feature	Value
Cable attribute	Suitable for chain link trunking
Protection class	IP65
Ambient temperature with flexible cable installation	-40 ... 75 °C
Ambient temperature	-50 ... 80 °C
Min. cable bending radius	100 mm
Cable structure	Shielded 3x(2 x 0,14 mm <sup>2</sup> ) + 2 x 0,5 mm <sup>2</sup>
Cable diameter	8.2 mm
Cable length	15 m
Materials note	Conforms to RoHS
Materials information, cable sheaths	TPE-U(PUR)