

Branching module FRM-H-3/4-D-MAXI

 

Part number: 162794

Classic - do not use for new projects

[Pneumatic manifold with 4 connections.](#)

[Modern alternatives can be found by entering the first four characters of the type code in the search field.](#)

FESTO

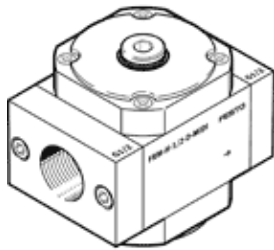

Data sheet

| Feature | Value |
|--|---|
| Assembly position | Any |
| Design structure | Branching module |
| Working pressure | 0.25 ... 16 bar |
| Standard nominal flow rate in main flow direction 1->2 | 13,500 l/min |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:-:-] Inert gases |
| Corrosion resistance classification CRC | 2 - Moderate corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Storage temperature | -10 ... 60 °C |
| Air purity class at output | Compressed air in accordance with ISO8573-1:2010 [7:-:-] Inert gases |
| Medium temperature | -10 ... 60 °C |
| Ambient temperature | -10 ... 60 °C |
| Product weight | 666 g |
| Pneumatic connection, port 1 | G3/4 |
| Pneumatic connection, port 2 | G3/4 |
| Pneumatic connection, port 3 | G3/4 |
| Pneumatic connection, port 4 | G1/4 |
| Materials note | Conforms to RoHS |
| Material housing | Zinc die-casting |