 



# Micro filter LFMA-1/2-H-A

Part number: 162815

FESTO

With 0.01µm filter cartridge, metal bowl guard.  
Discontinued, available through 2008

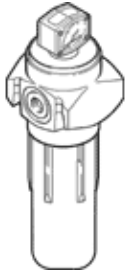

## Data sheet

Feature	Value
Assembly position	Vertical +/- 5°
Grade of filtration	0.01 µm
Filter efficiency	99.9999 %
Condensate drain	fully automatic
Design structure	Fiber filter
Differential pressure display	Pressure gauge
Inlet pressure 1	0 ... 16 bar
Standard nominal flow rate	1,100 l/min
Operating medium	Compressed air
Medium temperature	1.5 ... 60 °C
Residual oil content	0.01 mg/m <sup>3</sup>
Ambient temperature	-10 ... 60 °C
Product weight	1,120 g
Mounting type	with accessories
Pneumatic connection, port 1	G1/2
Pneumatic connection, port 2	G1/2
Materials note	Free of copper and PTFE
Materials information for filter	Boron silicate fiber
Materials information, housing	Zinc die-casting