

Fine filter combination

 

LFMBA-1/2-H-A

Part number: 162821

FESTO

Micro filter 1 μm for prefiltration and micro filter 0.01 μm , with metal bowl guard.

Discontinued, available through 2008

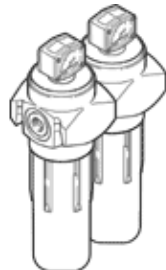

Data sheet

Feature	Value
Assembly position	Vertical +/- 5°
Grade of filtration	0.01 μm
Filter efficiency	99.9999 %
Condensate drain	fully automatic
Design structure	Fiber filter
Differential pressure display	Pressure gauge
Inlet pressure 1	0 ... 16 bar
Standard nominal flow rate	800 l/min
Operating medium	Filtered, unlubricated compressed air, 5 μm filtration Filtered, lubricated compressed air, 5 μm filtration
Medium temperature	1.5 ... 60 °C
Residual oil content	0.01 mg/m ³
Ambient temperature	-10 ... 60 °C
Product weight	2,300 g
Mounting type	with accessories
Pneumatic connection, port 1	G1/2
Pneumatic connection, port 2	G1/2
Materials information for filter	Boron silicate fiber
Materials information, housing	PA-reinforced
Materials information for bowl	Zinc die-casting