

 

# Linear actuator DGPL-11/16"- -PPV-A-KF-B

Part number: 162940

FESTO

For proximity sensing, rodless, with positive-locking connection between piston and actuator and adjustable end-position cushioning at both ends.

This product is only available if ordered from the Festo Corporation, USA.

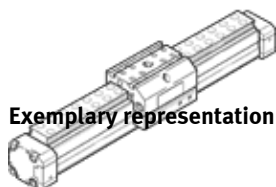

Exemplary representation

## Data sheet

| Feature              | Value   |
|----------------------|---|
| Stroke               | 10 ... 3,000 mm   |
| Piston diameter      | 11/16"  |
| Cushioning           | PPV: Pneumatic cushioning adjustable at both ends<br>YSR: Shock absorber, hard characteristic curve |
| Guide                | Recirculating ball bearing guide  |
| Driver principle     | positive-locking (slot)   |
| Working pressure     | 2 ... 8 bar   |
| Mode of operation    | double-acting   |
| Operating medium     | Compressed air in accordance with ISO8573-1:2010 [7::-:]  |
| Ambient temperature  | -10 ... 60 °C   |
| Cushioning length    | 16 mm   |
| Pneumatic connection | UNF10-32  |