


 
Linear actuator DGPL-2"- -PPV-A-KF-B

Part number: 162944

FESTO

For proximity sensing, rodless, with positive-locking connection between piston and actuator and adjustable end-position cushioning at both ends.

This product is only available if ordered from the Festo Corporation, USA.

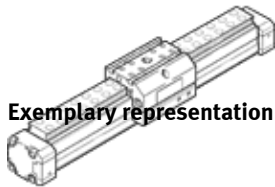

Exemplary representation

Data sheet

Feature	Value
Stroke	10 ... 3,000 mm
Piston diameter	2"
Cushioning	PPV: Pneumatic cushioning adjustable at both ends YSR: Shock absorber, hard characteristic curve
Guide	Recirculating ball bearing guide
Driver principle	positive-locking (slot)
Working pressure	1.5 ... 8 bar
Mode of operation	double-acting
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Ambient temperature	-10 ... 60 °C
Cushioning length	30 mm
Pneumatic connection	NPT1/4-18