

Connecting cable KMP3-25P-22-X


Part number: 163971
Product to be discontinued

FESTO

For valve manifold CPV.

The cable is available in lengths from 1 to 99 m.

Type to be discontinued. Available until 2018. See Support Portal for alternative products.

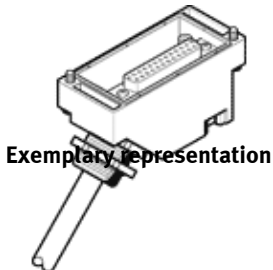

Data sheet

Feature	Value
Mounting type	with through hole
Assembly position	Any
Electrical connection	Plug socket Sub-D 25-pin
Nominal operating voltage DC	24 V
Permissible current load	3 A
Cable diameter	12 mm
Cable structure	24x0,25
Protection class	IP65
Ambient temperature	-30 ... 80 °C
Ambient temperature with flexible cable installation	-5 ... 80 °C
Materials note	Conforms to RoHS
Material cable sheath	PVC
Material housing	PA
Material seals	NBR
Material electrical contact	Copper alloy Gold plated