


Subbase PAML-CP-90-HP3-G34

Part number: 1651542

FESTO

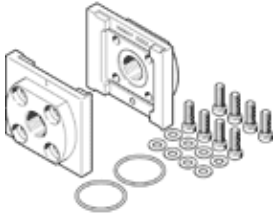

Data sheet

| Feature | Value |
|---|--|
| Size | 90 |
| Nominal diameter DN | 36 |
| Series | L |
| Operating pressure MPa | 0 ... 5 MPa |
| Working pressure | 0 ... 50 bar |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [-:-:-] |
| Corrosion resistance classification CRC | 2 - Moderate corrosion stress |
| PWIS conformity | VDMA24364-B2-L |
| Storage temperature | -10 ... 60 °C |
| Food-safe | See Supplementary material information |
| Medium temperature | 5 ... 60 °C |
| Ambient temperature | 5 ... 60 °C |
| Product weight | 750 g |
| Pneumatic connection, port 1 | G3/4 |
| Pneumatic connection, port 2 | G3/4 |
| Materials note | Conforms to RoHS |
| Material of connecting plate | Wrought Aluminum alloy |
| Material seals | NBR |
| Material screws | Stainless steel |