

 

# Intermediate pressure regulator plate LR-ZP-P-D-2-CT

Part number: 165860

FESTO

For ISO valves.

Run-out type. Available until 2010.

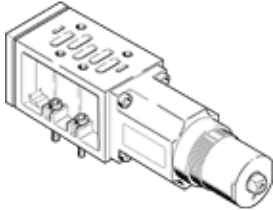

## Data sheet

Feature	Value
Based on the standard	ISO 5599-1
Integrated function	Pressure regulator
Design structure	Piston
Pressure control range	0 ... 12 bar
Inlet pressure 1	$\leq 14$ bar
Product weight	960 g
Materials note	Free of copper and PTFE
Materials information for seals	NBR
Materials information, housing	Aluminum die cast Steel