

# Heavy-duty guide HD-8- -

Part number: 170023


FESTO

## Configurable

To configure first add product to the shopping basket.

Depending on configuration, the technical data given on the data sheet and the relevant accessories might not match exactly for this product.

Type to be discontinued. Available until 2009.

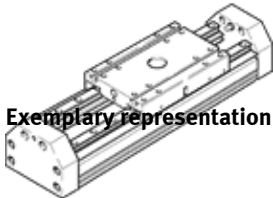

Exemplary representation

## Data sheet

~ConfIndependentDatasheet

Feature	Value
Size	8
Stroke	10 ... 1,080 mm
Assembly position	Any
Guide	Recirculating ball bearing guide
Design structure	Guide axis without actuator
Max. speed	3 m/s
Corrosion resistance classification CRC	0
Ambient temperature	-10 ... 60 °C
Max. force Fy	518 N
Max. force Fz	518 N
Max. torque Mx	12.6 Nm
Max. torque My	16.8 Nm
Max. torque Mz	16.8 Nm
Moving mass	195 g
Moving mass with 0 mm stroke	195 g
Additional weight per 10 mm stroke	33 g
Basic weight for 0 mm stroke	860 g
Materials information for guide component	Steel
Materials information, housing	Wrought Aluminum alloy Anodized