


Axis interface SPC-AIF-SUP-24DC

Part number: 171182

FESTO

[for axis interface string.](#)

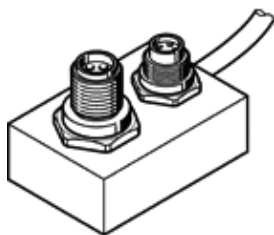

Data sheet

Feature	Value
Max. current consumption	3 A
Nominal operating voltage DC	24 V
Permissible voltage fluctuation	-5 % / +25 %
CE symbol (see declaration of conformity)	according to EU-EMV guideline
Continuous shock resistance per DIN/IEC 68, parts 2 - 82	Tested in accordance with severity level 2
Protection class	IP65 to IEC 60529
Vibration resistance per DIN/IEC 68, parts 2 - 6	Tested in accordance with severity level 2
Ambient temperature	0 ... 50 °C
Product weight	150 g
Electrical connection, load voltage	Plug Round design M12x1 5-pin
Electrical connection, AIF IN	Plug Round design M9 5-pin
Electrical connection, AIF OUT	Plug socket Round design M9 5-pin
Cable length	0.2 m