


Suction cup VAS-1-M3-NBR

Part number: 173437

FESTO

Sealing ring is not included in the scope of delivery.

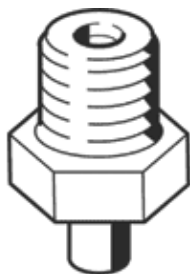

Data sheet

Feature	Value
Nominal size	0.4 mm
suction cup diameter	1 mm
Effective suction diameter	0.8 mm
Design structure	Vacuum connection at top round, standard
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Ambient temperature	-20 ... 80 °C
Breakaway force at 70% vacuum	0.035 N
Mounting thread	M3
suction cup mounting	M3
Vacuum connection	M3
Shore hardness	55 +/- 5
Materials information for screw-in stud	Zinc die-casting
Materials information for suction cup	NBR