


Valve manifold CPA10-VI

Part number: 173520

FESTO

Grid dimension 10 mm.

Depending on the configuration, the illustrations, the technical data on the data sheet and the relevant accessories might not exactly match this product.

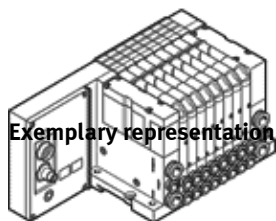

Data sheet

~ConfIndependentDatasheet

Feature	Value
Valve function	2x3/2 open/closed, monostable 2x3/2 closed, monostable 2x3/2 open, monostable 5/2 monostable 5/2 bistable 5/3 pressurized 5/3 exhausted 5/3 closed
Standard nominal flow rate	300 l/min
Working pressure	-0.9 ... 10 bar
Electrical connection	AS-Interface Individual connection Fieldbus Multipol
Max. number of valve positions	22
Max. no. of pressure zones	11
Electrical I/O system	Yes
Ambient temperature	-5 ... 50 °C
Width	10 mm
Protection class	IP65
Authorization	C-Tick
Grid dimension	10 mm
Type of actuation	electrical
Valve manifold type	12
Design structure	Piston slide
Pilot air supply	external Internal
Valve manifold structure	modular and expandable
Switching position indicator	LED
Pilot pressure	3 ... 8 bar
Nominal operating voltage DC	24 V
CE symbol (see declaration of conformity)	according to EU-EMV guideline
Corrosion resistance classification CRC	2
Medium temperature	-5 ... 50 °C