


Plug socket with cable KMEB-2-230-2,5

Part number: 174846

FESTO

Pre-assembled, for MEBH, MOEBH valves and N2 solenoids.

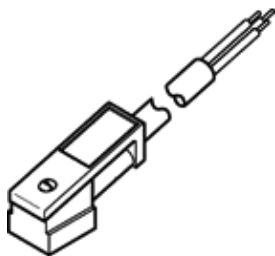

Data sheet

| Feature | Value |
|--|--|
| Mounting type | On solenoid valve with M2.5 central screw |
| Assembly position | Any |
| Product weight | 200 g |
| Electrical connection | 4-pin Plug socket angled Plug pattern type C to EN 175301-803 Per DIN EN 175301-803 |
| Nominal operating voltage, AC | 230 V |
| Protective earth connection | Available |
| Cable length | 2.5 m |
| Cable diameter | 6.2 mm |
| Cable structure | 3x0,75 |
| Protection class | IP65 to IEC 60529 |
| Ambient temperature | -20 ... 80 °C |
| CE symbol (see declaration of conformity) | according to EU low voltage guideline in accordance with EU RoHS directive |
| UKCA marking (see declaration of conformity) | To UK instructions for electrical equipment To UK RoHS instructions |
| PWIS conformity | VDMA24364-B2-L |
| Materials note | Conforms to RoHS |
| Material cable sheath | TPE-U(PUR) |
| Material housing | PA POM |
| Material electrical contact | Bronze |