


Plug socket with cable

KMEB-2-230-5

Part number: 174847

FESTO

Pre-assembled, for MEBH, MOEBH valves and N2 solenoids.

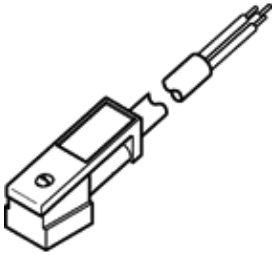

Data sheet

Feature	Value
Mounting type	On solenoid valve with M2.5 central screw
Assembly position	Any
Product weight	400 g
Electrical connection	4-pin Plug socket angled Plug pattern type C to EN 175301-803 Per DIN EN 175301-803
Nominal operating voltage, AC	230 V
Protective earth connection	Available
Cable length	5 m
Cable diameter	6.2 mm
Cable structure	3x0,75
Protection class	IP65 to IEC 60529
Ambient temperature	-20 ... 80 °C
CE symbol (see declaration of conformity)	according to EU low voltage guideline in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Material cable sheath	TPE-U(PUR)
Material housing	PA POM
Material electrical contact	Bronze